


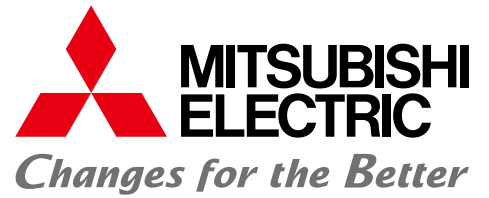

for a greener tomorrow



FACTORY AUTOMATION



# Graphic Operation Terminal GOT2000 Series Wide Model

Feb. 2021  
New Product Release

## NEW GOT 12.1 inch widescreen



12.1 inch type debut

**GOT2000** *Wide*  
Graphic Operation Terminal



# High resolution. Widen your experience.

The 12.1 inch WXGA widescreen display and enhanced specifications improve your system design.





# GOT2000 *Wide*

Graphic Operation Terminal

Actual size



**NEW**

GT25 wide model  
12.1" widescreen



GT2512-WXTSD  
Smart silver



GT2512-WXTBD  
Cool black

<b>WXGA</b> 1280 x 800	<b>TFT</b> 65536 colors	<b>DC power</b> 24 V DC
Ethernet 2 ports	RS-232	
RS-422/485	CC-Link IE Field Basic	
Wireless LAN communication unit interface*	Sound output interface	
Memory for storage (ROM) 32 MB	Memory for operation (RAM) 128 MB	

\* A wireless LAN communication unit is required separately.

## Specifications

### GOTs



Item	Specifications
	GT2512-WXTBD / GT2512-WXTSD
Display	12.1" widescreen, TFT color LCD, 65536 colors
Resolution	WXGA 1280 x 800 dots
Backlight	White LED
User memory	Memory for storage (ROM): 32 MB Memory for operation (RAM): 128 MB
Interface	Ethernet (2 ports), RS-232, RS-422/485, USB host (USB-A), USB device (USB Mini-B), sound output, SD memory card interface, wireless LAN communication unit interface*1
External dimensions	299(11.77) (W) x 219(8.62) (H) x 48(1.89) (D) mm(inch)
Panel cut dimensions	290.5(11.44) (W) x 210.5(8.29) (H) mm(inch)
Weight	1.7(3.7) kg(lb) (excluding a fitting)
Compatible software package	GT Works3 Version1.250L or later

\*1 A wireless LAN communication unit is required separately.



For the details of wide models,  
please refer to the Graphic Operation Terminal  
GOT2000 Series Wide Model catalog  
(L(NA)08461ENG).

### Various interfaces

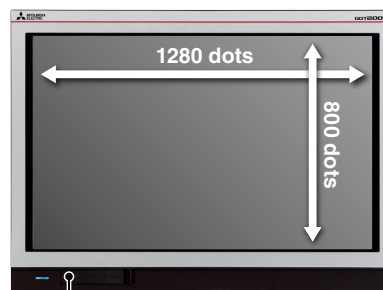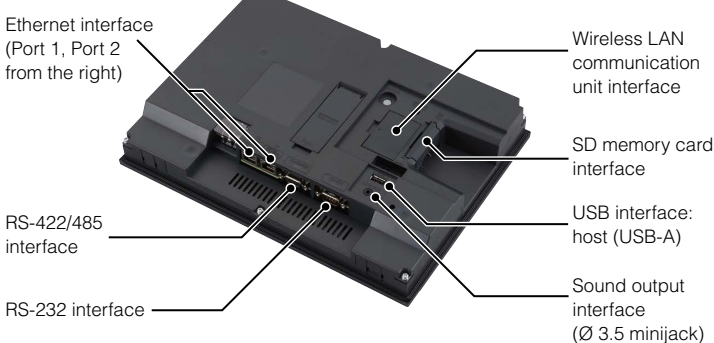

## Product list

### GOTs

Classification	Model	Screen size	Display section Display color	Panel color	Power
GT25 wide model	GT2512-WXTBD	12.1" WXGA (1280 x 800 dots)	TFT color 65536 colors	Black	24 V DC
	GT2512-WXTSD			Silver*1	

\*1 The lower part of the panel including the USB environmental protection cover is black.

### Options

Classification	Model	Specifications
Protective sheet	GT25-12WPSGC	For 12.1" wide models <ul style="list-style-type: none"> <li>• Antiglare type</li> <li>• Without a hole for the USB environmental protection cover*1</li> <li>• A set of 5 sheets</li> </ul>
	GT25-12WPSCC	
Protective cover for oil*2	GT21-12WPCO	For 12.1" wide models

\*1 The protective sheet is shaped not to cover the USB environmental protection cover.

\*2 Check if the protective cover for oil can be used in the actual environment before use. When using the cover, the front USB interface cannot be used.

The release date varies depending on the product and your region. For details, please contact your local sales office.

The actual color may differ slightly from the pictures in this catalog.  
The actual display may differ from what are shown on GOT screen images.

#### Precautions for safe use

To use the products given in this publication properly, always read the relevant manuals before beginning operation.

#### Trademarks and registered trademarks

All product and company names used herein are either trademarks or registered trademarks of their respective owners.

## MITSUBISHI ELECTRIC CORPORATION

HEAD OFFICE: TOKYO BLDG., 2-7-3, MARUNOUCHI, CHIYODA-KU, TOKYO 100-8310, JAPAN  
NAGOYA WORKS: 1-14, YADA-MINAMI 5, HIGASHI-KU, NAGOYA, JAPAN

Country/Region Sales office  
USA .....+1-847-478-2100  
Mexico .....+52-55-3067-7512  
Brazil .....+55-11-4689-3000  
China .....+86-21-2322-3030  
Taiwan .....+886-2-2299-2499  
Korea .....+82-2-3660-9569

Singapore .....+65-6473-2308  
Malaysia .....+60-3-7958-3544  
Indonesia .....+62-21-3192-6461  
Vietnam .....+84-28-3910-5945  
Thailand .....+66-2092-8600  
Philippines .....+63-(0)2-8256-8042

India .....+91-20-2710-2000  
Australia .....+61-2-9684-7777  
Germany .....+49-2102-486-0  
UK .....+44-1707-28-8780  
Italy .....+39-039-60531  
Spain .....+34-935-65-3131

France .....+33-1-55-68-55-68  
Czech Republic .....+420-255-719-200  
Turkey .....+90-216-969-2500  
Poland .....+48-12-347-65-00  
Russia .....+7-812-449-51-34  
South Africa .....+27-11-658-8100